

Sentry Basic CDU

CB-24VD/VY

Key Features

- > Power Distribution: 208V, 3-Phase, 20- and 30-Amp Power Input
- > Mid-Density Power Distribution: 24 IEC 60320 C13 outlets per enclosure
- > Branch Circuit Protection: Sentry CDUs meet UL 60950-1 requirements
- > Vertical Mounting: Zero-U button and bracket mounting options

Mid-Density Power Distribution

The Sentry Basic Cabinet (Power) Distribution Unit (CDU) product family provides a simple solution where reliable power distribution for equipment racks and other data center applications is needed. Basic CDU's provide both power distribution and branch circuit protection.

The Sentry Basic CDU offers different input connections to distribute power from 208V, 3-phase Delta or Wye, 20 or 30-Amp input feeds. The Sentry Basic CDU meets the criteria of Branch Circuit Protection by providing overcurrent protection with UL-listed circuit breakers for each branch circuit.

The Sentry Basic Cabinet Power Distribution Unit (CDU) family provides both a reliable and economical solution for your basic power needs.


Additional Benefits:



Branch Circuit Protection

The Sentry CDU Family meets the UL 60950-1 requirement for Branch Circuit Protections

- > UL-489 rated circuit breakers

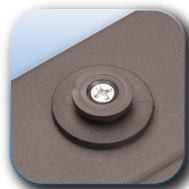

Button Mounting

All CDUs are also compatible with button & "keyhole" style mounting for cabinets. Several cabinet manufacturers are now using this method for installing power distribution units in the cabinet.



Model	Available Input Voltages	Amperage	Available Input Cord	Outlets	Dimensions (L x W x D)
CB-24VDD403-001	240V, 3-phase Delta, 50/60Hz	20A	NEMA L15-20P, Cord Set 10 ft (3 m)	(24) IEC 60320/C13	50.0 x 1.75 x 3.50 in. (1271 x 44 x 89 mm)
CB-24VDE403-001	240V, 3-phase Delta, 50/60Hz	30A	NEMA L15-30P, Cord Set 10 ft (3 m)	(24) IEC 60320/C13	50.0 x 1.75 x 3.50 in. (1271 x 44 x 89 mm)
CB-24VYL403-001	208V, 3-phase Wye, 50/60Hz	20A	NEMA L21-20P, Cord Set 10 ft (3 m)	(24) IEC 60320/C13	50.0 x 1.75 x 3.50 in. (1271 x 44 x 89 mm)
CB-24VYM403-001	208V, 3-phase Wye, 50/60Hz	30A	NEMA L21-30P, Cord Set 10 ft (3 m)	(24) IEC 60320/C13	50.0 x 1.75 x 3.50 in. (1271 x 44 x 89 mm)

Additional Specifications

Agency Approvals

- > US & Canada (cTUVus mark) to UL 60950-1:2003 and CAN/CSA 22.2 No. 60950-1-03
- > FCC Class A, Part 15
- > CE
- > EMC - EN 55022 Class A, EN 55024, CISPR 22 Class A

Branch Circuit Protection

- > Compliant to UL 60950-1



Server Technology

HEADQUARTERS - NORTH AMERICA

Server Technology, Inc.
 1040 Sandhill Drive
 Reno, NV 89521
 United States
 1.775.284.2000 Tel
 1.775.284.2065 Fax
 sales@servertech.com
 www.servertech.com
 www.servertechblog.com

EMEA

Server Technology Intl
 Sienna Court
 The Broadway
 Maidenhead
 Berkshire
 SL6 1NJ
 United Kingdom
 +44 (0) 1628 509053 Tel
 +44 (0) 1628 509100 Fax
 salesint@servertech.com

APAC

Server Technology Intl
 37th Floor, Singapore Land Tower
 50 Raffles Place
 Singapore 048623
 +65 (0) 6829 7008 Tel
 +65 (0) 6234 4574 Fax
 salesint@servertech.com